

NEW

Passepartout for compact networks



Unmanaged switches FL SWITCH 1000



Passepartout for compact networks

MBit/s
10
100
1000


5/8/16
Ports

22,5 mm

9-32VDC
&
18-30VAC

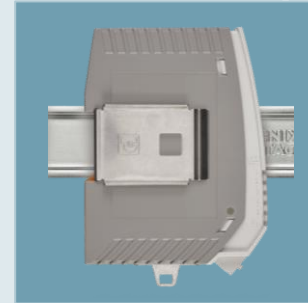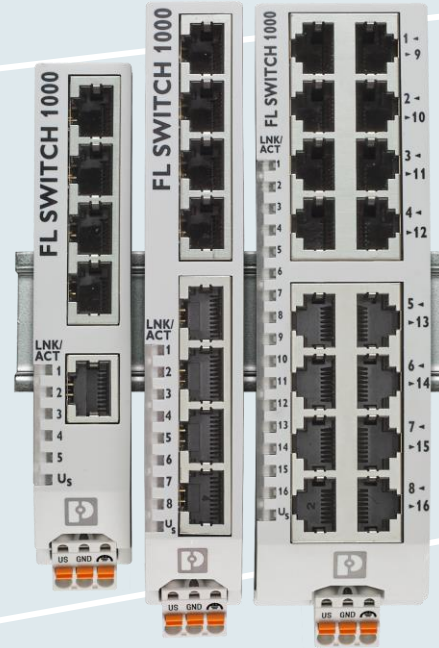

Plug
&
Play

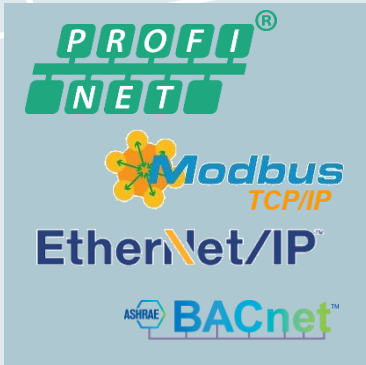

FL SWITCH 1000 Serie

Switch selector



Order number	Article description	Narrow housing			
		Copper ports		Fiber ports	
		10/100 Mbit/s	10/100/1000 Mbit/s	100 Mbit/s	100/1000 Mbit/s
1085039	FL SWITCH 1005N	5 x RJ45			
1084159	FL SWITCH 1004N-FX	4 x RJ45		1 x MM SC	
1085214	FL SWITCH 1004N-FX SM	4 x RJ45		1 x SM SC	
1085179	FL SWITCH 1004N-FX ST	4 x RJ45		1 x MM ST	
1085177	FL SWITCH 1004N-SFX	4 x RJ45		1 x SFP	
1085256	FL SWITCH 1008N	8 x RJ45			
1085176	FL SWITCH 1005N-2SFX	5 x RJ45		2 x SFP	
1085255	FL SWITCH 1016N	16 x RJ45			
1085254	FL SWITCH 1105N		5 x RJ45		
1085173	FL SWITCH 1104N-SFP		4 x RJ45		1 x SFP
1085243	FL SWITCH 1108N		8 x RJ45		
1085171	FL SWITCH 1105N-2SFP		5 x RJ45		2 x SFP
Product Accessories					
1085488	FL Panel Adapter 22.5	Adapter for flat wall mount			
1085486	FL Panel Adapter 40				
1085485	FL Din-Rail Adapter 22.5	Adapter for flat DIN rail mount			
1085484	FL Din-Rail Adapter 40				

Info-Page FL SWITCH 1000:

i Webcode: [#2528](#)

Order online right now :

NET-PRICE-PROMOTION 2021
(excl. VAT, only while stocks last)








E-Shop



FL SWITCH 1000 Serie

Prices & technical data – copper ports








***NET-PRICE-PROMOTION 2021**
(excl. VAT, only while stocks last)

					
CHF*	53.53	79.93	156.38	90.35	138.33
Description	FL SWITCH 1005N	FL SWITCH 1008N	FL SWITCH 1016N	FL SWITCH 1105N	FL SWITCH 1108N
Article & Weblink	1085039	1085256	1085255	1085254	1085243
Ports	5 RJ45	8 RJ45	16 RJ45	5 RJ45	8 RJ45
Speed	10/100 Mbit/s	10/100 Mbit/s	10/100 Mbit/s	10/100/ 1000 Mbit/s	10/100/ 1000 Mbit/s
Input Voltage	9-32V DC and 18-30V AC	9-32V DC and 18-30V AC	9-32V DC and 18-30V AC	9-32V DC and 18-30V AC	9-32V DC and 18-30V AC
Approvals	UL 61010, 62368, C1D2	UL 61010, 62368, C1D2	UL 61010, 62368, C1D2	UL 61010, 62368, C1D2	UL 61010, 62368, C1D2
Temperature Range	-10 to 60C	-10 to 60C	-10 to 60C	-10 to 60C	-10 to 60C
Dimensions (W x H x D)	22.5 x 117 x 84 mm	22.5 x 140.4 x 92 mm	40 x 140.4 x 92mm	22.5 x 117 x 84 mm	22.5 x 140.4 x 92 mm

FL SWITCH 1000 Serie


Prices & technical data – fiberoptic ports

***NET-PRICE-PROMOTION 2021**
(excl. VAT, only while stocks last)

							
CHF*	104.25	104.25	139.00	59.08	91.05	100.78	155.00
Description	FL SWITCH 1004N-FX	FL SWITCH 1004N-FX ST	FL SWITCH 1004N-FX SM	FL SWITCH 1004N-SFX	FL SWITCH 1005N-2SFX	FL SWITCH 1104N-SFP	FL SWITCH 1105N-2SFP
Article & Weblink	1084159	1085179	1085214	1085177	1085176	1085173	1085171
Ports	4 RJ45, 1FX	4 RJ45, 1 FX ST	4 RJ45, 1 FX SM	4 RJ45, 1 SFX	5 RJ45, 2 SFX	4 RJ45, 1 SFP	5 RJ45, 2 SFP
Speed	10/100 Mbit/s	10/100 Mbit/s	10/100 Mbit/s	10/100 Mbit/s	10/100 Mbit/s	10/100/ 1000 Mbit/s	10/100/ 1000 Mbit/s
Input Voltage	9-32V DC and 18-30V AC	9-32V DC and 18-30V AC	9-32V DC and 18-30V AC	9-32V DC and 18-30V AC	9-32V DC and 18-30V AC	9-32V DC and 18-30V AC	9-32V DC and 18-30V AC
Approvals	UL 61010, 62368, C1D2	UL 61010, 62368, C1D2	UL 61010, 62368, C1D2	UL 61010, 62368, C1D2	UL 61010, 62368, C1D2	UL 61010, 62368, C1D2	UL 61010, 62368, C1D2
Temperature Range	-10 to 60C	-10 to 60C	-10 to 60C	-10 to 60C	-10 to 60C	-10 to 60C	-10 to 60C
Dimensions (W x H x D)	22.5 x 117 x 84 mm	22.5 x 117 x 84 mm	22.5 x 117 x 84 mm	22.5 x 117 x 84 mm	22.5 x 140.4 x 92mm	22.5 x 117 x 84 mm	22.5 x 140.4 x 92mm

FL SWITCH 1000



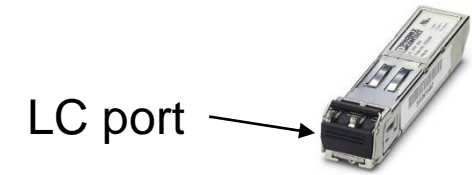

Small form-factor pluggable (SFP) options



	*Gross list prices 2021 April			SFP selector for different switch families							
Web-Link	CHF*	Art.-Nr.	1000PoE	1000	1100	2200	2300	3000	4000	7000	GHS
FL SFP FX MM / 1310nm / 2km / 100MBit/s	129.20	2891081	X	X	X	X	X	X		X	
FL SFP FX SM SM / 1310nm / 40km / 100MBit/s	224.40	2891082	X	X	X	X	X	X		X	
FL SFP FE WDM20 SET SM / 1310nm / 20km / 100MBit/s	1087.50	2702439	X	X	X	X	X	X		X	
FL SFP SX MM / 850nm / 1km / 1000MBit/s	203.00	2891754	X		X		X		X	X	X
FL SFP SX2 MM / 1310nm / 2km / 1000MBit/s	290.00	2702397	X		X		X		X	X	X
FL SFP LX10-B SM / 1310nm / 10km / 1000MBit/s	217.50	1025401	X		X		X		X	X	X
FL SFP LX40 SM / 1310nm / 40km / 1000MBit/s	638.00	1113081	X		X		X		X	X	X
FL SFP LX SM / 1310nm / 30km / 1000MBit/s	319.00	2891767	X		X		X		X	X	X
FL SFP LH SM / 1550nm / 80km / 1000MBit/s	1740.00	2989912	X		X		X		X	X	X
FL SFP WDM10 SET SM / 1310nm / 10km / 1000MBit/s	1305.00	2702442	X		X		X		X	X	X
FL SFP GT RJ45-Port / 100m / 1000MBit/s	362.50	2989420	X		X		X		X	X	X

FL SWITCH 1000 Serie

Mounting plate for DIN-rail and panel

				
CHF*	15.20	15.20	11.40	11.40
Description	FL DIN-RAIL ADAPTER 22.5	FL DIN-RAIL ADAPTER 40	FL PANEL ADAPTER 22.5	FL PANEL ADAPTER 40
Article & Weblink	1085485	1085484	1085488	1085486
Type	DIN-RAIL	DIN-RAIL	PANEL	PANEL
Compatible 1000er	5-Port-Switches 8-Port-Switches	16-Port-Switches	5-Port-Switches 8-Port-Switches	16-Port-Switches

***NET-PRICE-PROMOTION 2021** (excl. VAT, only while stocks last)