


CABLE-EC56/F/F/0,34/S/...

Description

Assembled round cable with ELCO/EDAC connector on both sides (1:1 connection). This cable can be used as mating part of the electronics or controller module having male ELCO (8016 series) and EDAC (516 series) or equivalent connector.

Following features characterize these cables:

- ELCO/EDAC connectors to connect to ELCO interface boards
- Lineup of VARIOFACE termination boards
- Standard length in variables of 5 meters
- Variable lengths available upon request
- Braided shield is routed to a separate cable end fitted with a ferrule
- According to UL AWM, style 2464 / CSA

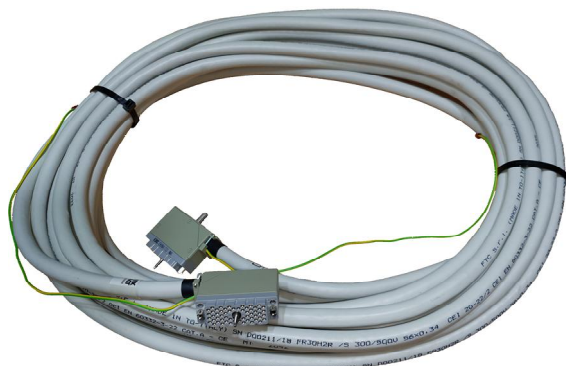

Note: Picture shows a similar product

Order Data

Type / Model No.	Article No. / Order No.
CABLE-EC56/F/F/0,34/S/05M	5013001
CABLE-EC56/F/F/0,34/S/10M	5013002
CABLE-EC56/F/F/0,34/S/15M	5013003
CABLE-EC56/F/F/0,34/S/20M	5013004
CABLE-EC56/F/F/0,34/S/25M	5013005
CABLE-EC56/F/F/0,34/S/30M	5013006
CABLE-EC56/F/F/0,34/S/35M	5013007
CABLE-EC56/F/F/0,34/S/40M	5013008
CABLE-EC56/F/F/0,34/S/45M	5013009
CABLE-EC56/F/F/0,34/S/50M	5013010

Technical Data

Cable

Cable	Assembled shielded round cable
Make	Klasing
No. of core	56 Cores
Conductor cross section	0.34mm ²
Core diameter (approx.)	1.3mm
Conductor resistance	56 W/Km at 20°C
Core stranding/construction	19 x 0.15mm stranded copper wires (AWG22)
Outer diameter	14.10mm
Maximum permissible operating Voltage	25V AC/60V DC
Insulation Resistance	>100M Ohm x km
Overall Shield	Tinned copper braid – coverage >80%
Inner sheath material	Semi-rigid PVC (UL-style 1061)
Inner core color	Color coded to DIN 47100 without repetition
Outer sheath material	PVC class 43
Outer sheath color	Grey (RAL 7035)
Flammability	Flame Retardant to IEC 60332-3-2
Operating temperature range	-20°C to +80°C

Connector

Type	Rectangular female type connector (on both ends)
Make	EDAC 516 series
No. of positions used	56
Receptacle insulation material	Polycarbonate, Grey color
Cover material	Die-cast zinc finished with grey enamel paint

CABLE-EC56/F/F/0,34/S/...

Accessory

Type / Model No.	Article No. / Order No.	Item Description	Scope of Supply
UMK- EC56/56-XOR	2975900	56 pos. VARIOFACE module with pin strip 8016 right above	no
UMK- EC56/56-XOL	2975890	56 pos. VARIOFACE module with pin strip 8016 left above	no

Connector orientation and pinning details

External view

