




 LIMITED LIFETIME
WARRANTY
BUILD WITH CONFIDENCE

PTCB series

Narrow electronic circuit breakers for 24 V DC


Narrow electronic circuit breakers

At 6.2 mm wide, the PTCB series is ideally suited for simple, space-saving potential distribution: these single-channel electronic circuit breakers for 24 V DC applications can be bridged to the CLIPLINE complete terminal block system, and offer a setting range from 1 to 8 amperes.

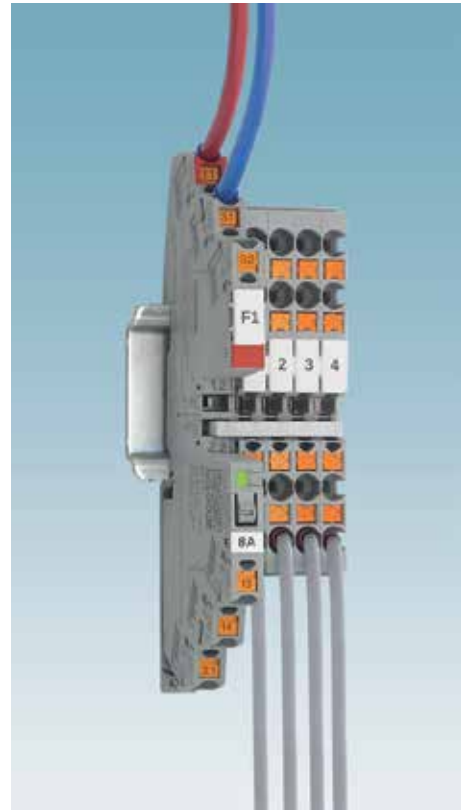

Your advantages

- ✓ Simplify application designs using bridging option to CLIPLINE complete terminal block system
- ✓ More space in the control cabinet: narrowest protection with a width of just 6.2mm
- ✓ Reduce inventory requirements with adjustable current values

The product range						
		Nominal current	Operating voltage	Part description	Order number	NEC Class 2
	Programmable current setting	1-3 A	18...27.5 V DC	PTCB E1 24DC/1-3A NO	2909909	✓
		1-8 A	18...30 V DC	PTCB E1 24DC/1-8A NO	2908262	
	Fixed current setting	1 A	18...30 V DC	PTCB E1 24DC/1A NO	2909902	✓
		2 A	18...30 V DC	PTCB E1 24DC/2A NO	2909903	✓
		3 A	18...27.5 V DC	PTCB E1 24DC/3A NO	2909904	✓
		4 A	18...30 V DC	PTCB E1 24DC/4A NO	2909906	
		6 A	18...30 V DC	PTCB E1 24DC/6A NO	2909908	
		8 A	18...30 V DC	PTCB E1 24DC/8A NO	2909910	

USA

Phoenix Contact USA, Inc.
P.O. Box 4100
Harrisburg, PA 17111-0100
Phone: 800-888-7388
717-944-1300
Technical Service: 800-322-3225
Fax: 717-944-1625
E-mail: info@phoenixcon.com
Website: www.phoenixcontact.com

To learn more, please visit: www.phoenixcontact.com/ptcb